

SIEMENS


Question:

Does the SIMODRIVE 611 A commissioning software HSA/AM V3.3 - that was developed at the DOS level - also run under Windows XP?

Answer:

It is possible to install the commissioning software HSA/AM V3.3 under Windows XP. However, this then runs with instructions that cannot be read. Procedure:

- Install installation floppy disk 1/2 into drive A:
- Call up Start/Programs/Accessories/Command Prompt. The following is displayed:

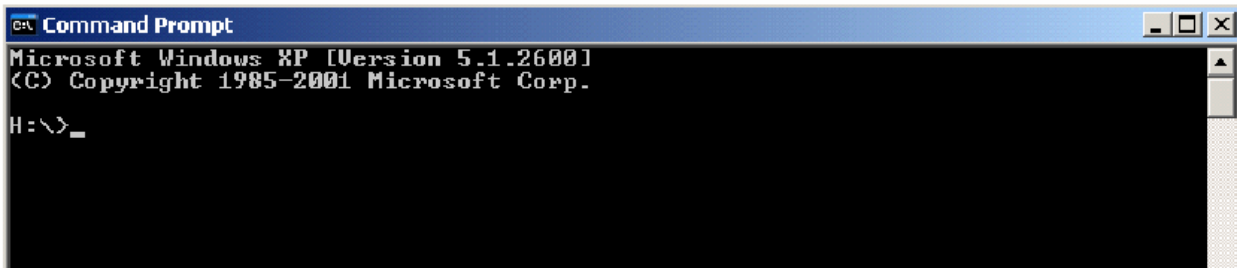

```
e:\ Command Prompt
Microsoft Windows XP [Version 5.1.2600]
(C) Copyright 1985-2001 Microsoft Corp.
H:\>_
```

- Enter A: "Enter"
- Enter "install" "Enter": The following is displayed:



```
A:\>ECHO OFF
Bitte geben Sie ein:  INSTALL DEUTSCH
Please enter:         INSTALL ENGLISH
Tapez Svp:           INSTALL FRANCAIS
Immetta per favore:  INSTALL ITALIANO
Introducir los datos: INSTALL ESPAGNOL
A:\>_
```

- Select the required language: e.g. for English: "Install English" "Enter"
- The following is displayed:



```
A:\>ECHO OFF
[37;40m[0m[H[2J[37;44m=====IBS Installation=====
[37;40m[3;10HIBS Inbetriebnahmesoftware für SIMODRI
UE 611-A[5;10HCopyright (C) Siemens AG 1994 All Rights Reserved+[20;19H|
[22;19H| Abbrechen mit          Weiter mit          RETU
[9;10HVerzeichnis:[7m[11;10HC:\IBS
[11;16H
```

SIEMENS

- Press "Enter": The "IBS" [commissioning] directory is set up on drive C: and the installation process starts.
- After the installation stops, the following is shown on the screen:

```

<[5;10HKopiere: SIEM0310.1PA <[5;10HKopiere: ANW1.1PA <[5;10HKopiere: HSA_0
300.HEX <[5;10HKopiere: HSA_0310.HEX <[5;10HKopiere: HSA_0320.HEX <[5;10HKopiere
: AMM_0210.HEX <[5;10HKopiere: AMM_0310.HEX <[0m<[H<[2J<[37;44m
=====IBS Installation=====
+ [37;40m<[5;10HKop
iere: IBS.TXT <[5;10HKopiere: IBS.HLP <[5;10HKopiere: PB0210.1PH <[5
;10HKopiere: PB0210.1PH <[5;10HKopiere: PB0210.1PH <[5;10HKopiere: PB0240.1P
H <[5;10HKopiere: PB0300.1PH <[5;10HKopiere: PB0310.1PH <[5;10HKopiere: PB
0310.1PH <[5;10HKopiere: PB0130.1PA <[5;10HKopiere: PB0200.1PA <[5;10HKopi
ere: PB0200.1PA <[5;10HKopiere: PB0310.1PA <[5;10HKopiere: README.TXT <[5;
10HKopiere: PB0210.1PH <[5;10HKopiere: PB0210.1PH <[5;10HKopiere: PB0210.1PH
<[5;10HKopiere: PB0240.1PH <[5;10HKopiere: PB0300.1PH <[5;10HKopiere: PB0
310.1PH <[5;10HKopiere: PB0310.1PH <[5;10HKopiere: PB0130.1PA <[5;10HKopi
ere: PB0200.1PA <[5;10HKopiere: PB0200.1PA <[5;10HKopiere: PB0310.1PA <[0m<
[H<[2J<[37;44m
=====IBS Installation=====
+ [37;40m<[4;25H | <[5;25H | <[7;25H | <[11;10HBitte Diskette einlegen:<[13;10
HInstallationsdiskette 2<[15;10HLaufwerk A<[20;19H | <[21;19H | Weiter mit
n mit <[23;19H | RETURN |<[22;19H | Abbreche
|<[8;25H |<[6;25H |

```

- Remove floppy disk 1/2 from the drive, insert floppy disk 2/2 and confirm with "Enter".
- The installation is now completed. After it has been completed the following is displayed:

```

e: PB0210.1PH <[5;10HKopiere: PB0240.1PH <[5;10HKopiere: PB0300.1PH <[5;10
HKopiere: PB0310.1PH <[5;10HKopiere: PB0310.1PH <[5;10HKopiere: PB0130.1PA
<[5;10HKopiere: PB0200.1PA <[5;10HKopiere: PB0200.1PA <[5;10HKopiere: PB031
0.1PA <[0m<[H<[2J<[37;44m
=====IBS Installation=====
+ [37;40m<[5;10HKopiere: IBS.TXT <[5;10HKopiere: I
BS.HLP <[5;10HKopiere: PB0210.1PH <[5;10HKopiere: PB0210.1PH <[5;10HKop
iere: PB0210.1PH <[5;10HKopiere: PB0240.1PH <[5;10HKopiere: PB0300.1PH <[5
;10HKopiere: PB0310.1PH <[5;10HKopiere: PB0310.1PH <[5;10HKopiere: PB0130.1P
A <[5;10HKopiere: PB0200.1PA <[5;10HKopiere: PB0200.1PA <[5;10HKopiere: PB
0310.1PA <[0m<[H<[2J<[37;44m
=====IBS Installation=====
+ [37;40m<[5;10HKopiere: IBS.TXT <[5;10HKopiere
: IBS.HLP <[5;10HKopiere: PB0210.1PH <[5;10HKopiere: PB0210.1PH <[5;10H
Kopiere: PB0210.1PH <[5;10HKopiere: PB0240.1PH <[5;10HKopiere: PB0300.1PH
<[5;10HKopiere: PB0310.1PH <[5;10HKopiere: PB0310.1PH <[5;10HKopiere: PB0130
.1PA <[5;10HKopiere: PB0200.1PA <[5;10HKopiere: PB0200.1PA <[5;10HKopiere:
PB0310.1PA <[0m<[H<[2J<[37;44m
=====IBS Installatio
n=====
+ [37;40m<[5;10HStarten Sie die Software mit: IBS
<611HSA;611AMM> [/M]<[9;10Hviel Erfolg mit Ihrer IBS-Software!<[13;0H
C:\IBS>

```

- Now, the program can be started with the command "ibs 611hsa" (or "ibs 611amm" for encoderless operation) "Enter".
- Or close the DOS window with "exit" "Enter".

Comment: The screen shots above show the installation in German.