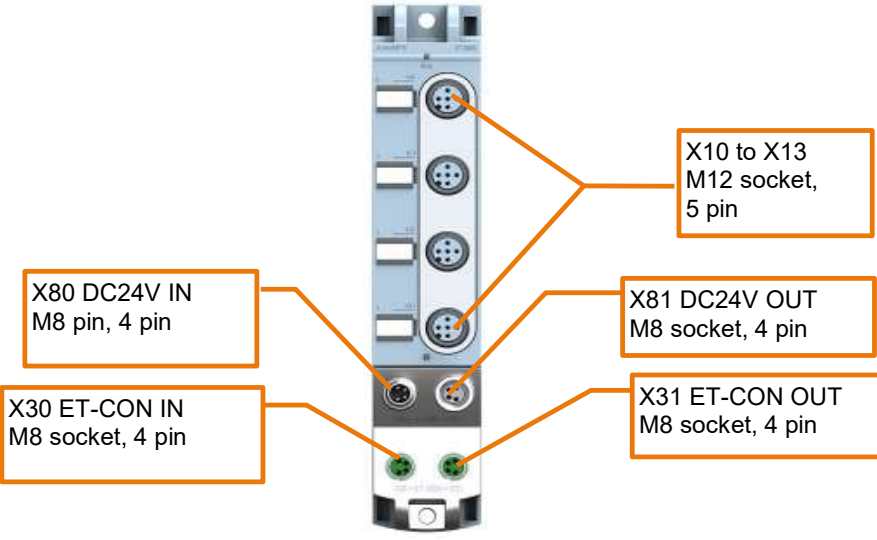


ET 200AL		
<b>analog modules</b>		
AI 4xU/I/RTD, 4xM12		6ES7144-5KD00-0BA0
AI 4xRTD/TC, 4xM12		6ES7144-5KD50-0AB0
AQ 4xU/I, 4xM12		6ES7145-5ND00-0BA0
		
<b>Interfaces</b>		<b>Order number</b>
<b>X10 to X13 (M12 socket, 5 pin)</b>		
<b>Miscellaneous</b>		
M12 cover caps		3RX9802-0AA00
M12 cover caps		3RK1901-1KA00
<b>X80 DC 24V IN (M8 pin, 4 pin)</b>		
<b>Non-assembled connectors</b>		
M8 power connector, socket insert, 4 pin		6ES7194-2AC00-0AA0
<b>Pre-assembled cables</b>		
Power cable M8, pre-assembled at both ends with M8 plug and M8 socket, 4 core	0,19 m	6ES7194-2LH02-1AA0
	0,3 m	6ES7194-2LH03-1AA0
	1,0 m	6ES7194-2LH10-1AA0
	2,0 m	6ES7194-2LH20-1AA0
	5,0 m	6ES7194-2LH50-1AA0
	10,0 m	6ES7194-2LN10-1AA0
	15,0 m	6ES7194-2LN15-1AA0
Power cable M8, PUR cable, pre-assembled at both ends with M8 plug and M8 socket, 4 core	0,19 m	6ES7194-2MH02-1AA0
	0,3 m	6ES7194-2MH03-1AA0
	1,0 m	6ES7194-2MH10-1AA0
	2,0 m	6ES7194-2MH20-1AA0
	5,0 m	6ES7194-2MH50-1AA0
	10,0 m	6ES7194-2MN10-1AA0
	15,0 m	6ES7194-2MN15-1AA0
Power cable M8, pre-assembled at both ends with M8 plug (angled) and M8 socket (angled), 4 core	0,3 m	6ES7194-2LH03-1AB0
	1,0 m	6ES7194-2LH10-1AB0
	2,0 m	6ES7194-2LH20-1AB0
	5,0 m	6ES7194-2LH50-1AB0
	10,0 m	6ES7194-2LN10-1AB0
	15,0 m	6ES7194-2LN15-1AB0

Power cable M8, PUR cable, pre-assembled at both ends with M8 plug (angled) and M8 socket (angled), 4 core	0,3 m	6ES7194-2MH03-1AB0
	1,0 m	6ES7194-2MH10-1AB0
	2,0 m	6ES7194-2MH20-1AB0
	5,0 m	6ES7194-2MH50-1AB0
	10,0 m	6ES7194-2MN10-1AB0
	15,0 m	6ES7194-2MN15-1AB0
Power cable M8, pre-assembled at one end with M8 socket, 4 core	2,0 m	6ES7194-2LH20-1AC0
	5,0 m	6ES7194-2LH50-1AC0
	10,0 m	6ES7194-2LN10-1AC0
	15,0 m	6ES7194-2LN15-1AC0
Power cable M8, PUR cable, pre-assembled at one end with M8 socket, 4 core	2,0 m	6ES7194-2MH20-1AC0
	5,0 m	6ES7194-2MH50-1AC0
	10,0 m	6ES7194-2MN10-1AC0
	15,0 m	6ES7194-2MN15-1AC0
<b>X81 DC 24V OUT (M8 socket, 4 pin)</b>		
<b>Non-assembled connectors</b>		
M8 Power connector, pin insert, 4 pin		6ES7194-2AA00-0AA0
<b>Pre-assembled cables</b>		
Power cable M8, pre-assembled at both ends with M8 plug and M8 socket, 4 core	0,19 m	6ES7194-2LH02-1AA0
	0,3 m	6ES7194-2LH03-1AA0
	1,0 m	6ES7194-2LH10-1AA0
	2,0 m	6ES7194-2LH20-1AA0
	5,0 m	6ES7194-2LH50-1AA0
	10,0 m	6ES7194-2LN10-1AA0
Power cable M8, PUR cable, pre-assembled at both ends with M8 plug and M8 socket, 4 core	0,19 m	6ES7194-2MH02-1AA0
	0,3 m	6ES7194-2MH03-1AA0
	1,0 m	6ES7194-2MH10-1AA0
	2,0 m	6ES7194-2MH20-1AA0
	5,0 m	6ES7194-2MH50-1AA0
	10,0 m	6ES7194-2MN10-1AA0
Power cable M8, pre-assembled at both ends with M8 plug (angled) and M8 socket (angled), 4 core	0,3 m	6ES7194-2LH03-1AB0
	1,0 m	6ES7194-2LH10-1AB0
	2,0 m	6ES7194-2LH20-1AB0
	5,0 m	6ES7194-2LH50-1AB0
	10,0 m	6ES7194-2LN10-1AB0
	15,0 m	6ES7194-2LN15-1AB0
Power cable M8, PUR cable, pre-assembled at both ends with M8 plug (angled) and M8 socket (angled), 4 core	0,3 m	6ES7194-2MH03-1AB0
	1,0 m	6ES7194-2MH10-1AB0
	2,0 m	6ES7194-2MH20-1AB0
	5,0 m	6ES7194-2MH50-1AB0
	10,0 m	6ES7194-2MN10-1AB0
	15,0 m	6ES7194-2MN15-1AB0
Power cable M8, pre-assembled at one end with M8 socket, 4 core	2,0 m	6ES7194-2LH20-1AC0
	5,0 m	6ES7194-2LH50-1AC0
	10,0 m	6ES7194-2LN10-1AC0
	15,0 m	6ES7194-2LN15-1AC0
Power cable M8, PUR cable, pre-assembled at one end with M8 socket, 4 core	2,0 m	6ES7194-2MH20-1AC0
	5,0 m	6ES7194-2MH50-1AC0
	10,0 m	6ES7194-2MN10-1AC0
	15,0 m	6ES7194-2MN15-1AC0
<b>Miscellaneous</b>		
M8 cover caps		3RK1901-1PN00

<b>X30 ET-CON IN (M8 socket, 4 pin)</b>		
<b>Non-assembled connectors</b>		
M8 connector for ET-Connection, 4 pin, shield		6ES7194-2AB00-0AA0
<b>Pre-assembled cables</b>		
Bus cable for ET-Connection M8, pre-assembled at both ends with 2 x M8 connectors, 4 core, shield	0,19 m	6ES7194-2LH02-0AA0
	0,3 m	6ES7194-2LH03-0AA0
	1,0 m	6ES7194-2LH10-0AA0
	2,0 m	6ES7194-2LH20-0AA0
	5,0 m	6ES7194-2LH50-0AA0
	10,0 m	6ES7194-2LN10-0AA0
	15,0 m	6ES7194-2LN15-0AA0
Bus cable for ET-Connection M8, PUR cable, pre-assembled at both ends with 2 x M8 connectors, 4 core, shield	0,19 m	6ES7194-2MH02-0AA0
	0,3 m	6ES7194-2MH03-0AA0
	1,0 m	6ES7194-2MH10-0AA0
	2,0 m	6ES7194-2MH20-0AA0
	5,0 m	6ES7194-2MH50-0AA0
	10,0 m	6ES7194-2MN10-0AA0
	15,0 m	6ES7194-2MN15-0AA0
Bus cable for ET-Connection M8, pre-assembled at both ends with 2 x M8 connectors, angled, 4 core, shield	0,3 m	6ES7194-2LH03-0AB0
	1,0 m	6ES7194-2LH10-0AB0
	2,0 m	6ES7194-2LH20-0AB0
	5,0 m	6ES7194-2LH50-0AB0
	10,0 m	6ES7194-2LN10-0AB0
	15,0 m	6ES7194-2LN15-0AB0
Bus cable for ET-Connection M8, PUR cable, pre-assembled at both ends with 2 x M8 connectors, angled, 4 core, shield	0,3 m	6ES7194-2MH03-0AB0
	1,0 m	6ES7194-2MH10-0AB0
	2,0 m	6ES7194-2MH20-0AB0
	5,0 m	6ES7194-2MH50-0AB0
	10,0 m	6ES7194-2MN10-0AB0
	15,0 m	6ES7194-2MN15-0AB0
Bus cable for ET-Connection M8, pre-assembled at one end with M8 connector, 4 core, shield	2,0 m	6ES7194-2LH20-0AC0
	5,0 m	6ES7194-2LH50-0AC0
	10,0 m	6ES7194-2LN10-0AC0
	15,0 m	6ES7194-2LN15-0AC0
Bus cable for ET-Connection M8, PUR cable, pre-assembled at one end with M8 connector, 4 core, shield	2,0 m	6ES7194-2MH20-0AC0
	5,0 m	6ES7194-2MH50-0AC0
	10,0 m	6ES7194-2MN10-0AC0
	15,0 m	6ES7194-2MN15-0AC0
<b>Miscellaneous</b>		
Connection cable for ET-Connection, pre-assembled with 2 x M8 socket, 4 core, shielded	0,2 m	6ES7194-2LH02-0AD0
Connection cable for ET-Connection, PUR cable, pre-assembled with 2 x M8 socket, 4 core, shielded	0,2 m	6ES7194-2MH02-0AD0
M8 cover caps		3RK1901-1PN00
<b>X31 ET-CON OUT (M8 socket, 4 pin)</b>		
<b>Non-assembled connectors</b>		
M8 connector for ET-Connection, 4 pin, shield		6ES7194-2AB00-0AA0
<b>Pre-assembled cables</b>		
Bus cable for ET-Connection M8, pre-assembled at both ends with 2 x M8 connectors, 4 core, shield	0,19 m	6ES7194-2LH02-0AA0
	0,3 m	6ES7194-2LH03-0AA0
	1,0 m	6ES7194-2LH10-0AA0
	2,0 m	6ES7194-2LH20-0AA0
	5,0 m	6ES7194-2LH50-0AA0
	10,0 m	6ES7194-2LN10-0AA0
	15,0 m	6ES7194-2LN15-0AA0

Bus cable for ET-Connection M8, PUR cable, pre-assembled at both ends with 2 x M8 connectors, 4 core, shield	0,19 m	6ES7194-2MH02-0AA0
	0,3 m	6ES7194-2MH03-0AA0
	1,0 m	6ES7194-2MH10-0AA0
	2,0 m	6ES7194-2MH20-0AA0
	5,0 m	6ES7194-2MH50-0AA0
	10,0 m	6ES7194-2MN10-0AA0
	15,0 m	6ES7194-2MN15-0AA0
Bus cable for ET-Connection M8, pre-assembled at both ends with 2 x M8 connectors, angled, 4 core, shield	0,3 m	6ES7194-2LH03-0AB0
	1,0 m	6ES7194-2LH10-0AB0
	2,0 m	6ES7194-2LH20-0AB0
	5,0 m	6ES7194-2LH50-0AB0
	10,0 m	6ES7194-2LN10-0AB0
Bus cable for ET-Connection M8, PUR cable, pre-assembled at both ends with 2 x M8 connectors, angled, 4 core, shield	0,3 m	6ES7194-2MH03-0AB0
	1,0 m	6ES7194-2MH10-0AB0
	2,0 m	6ES7194-2MH20-0AB0
	5,0 m	6ES7194-2MH50-0AB0
	10,0 m	6ES7194-2MN10-0AB0
Bus cable for ET-Connection M8, pre-assembled at one end with M8 connector, 4 core, shield	15,0 m	6ES7194-2MN15-0AB0
	2,0 m	6ES7194-2LH20-0AC0
	5,0 m	6ES7194-2LH50-0AC0
	10,0 m	6ES7194-2LN10-0AC0
	15,0 m	6ES7194-2LN15-0AC0
Bus cable for ET-Connection M8, PUR cable, pre-assembled at one end with M8 connector, 4 core, shield	2,0 m	6ES7194-2MH20-0AC0
	5,0 m	6ES7194-2MH50-0AC0
	10,0 m	6ES7194-2MN10-0AC0
	15,0 m	6ES7194-2MN15-0AC0
<b>Miscellaneous</b>		
Connection cable for ET-Connection, pre-assembled with 2 x M8 socket, 4 core, shielded	0,2 m	6ES7194-2LH02-0AD0
Connection cable for ET-Connection, PUR cable, pre-assembled with 2 x M8 socket, 4 core, shielded	0,2 m	6ES7194-2MH02-0AD0
M8 cover caps		3RK1901-1PN00
<b>Universal accessories</b>		
other cable length as above-mentioned		on request
Stripping Tool ET-Connection		6ES7194-2KA00-0AA0
Identification labels 10x5mm, RAL9016		6ES7194-2BA00-0AA0
torque wrenches set M8/M12, variable adjustable		www.peres.de PER091