

фронтальный поворотный привод стандарт МЭК IP30/40 принадлежность для:
3VA1 250



версия		
торговая марка изделия	SETRON	
принадлежности	фронтальный поворотный привод	
Общие технические данные		
степень защиты IP	IP30	
Механическая конструкция		
высота	75 mm	
ширина	105 mm	
глубина	95 mm	
Сертификаты		
General Product Approval	EMV	Test Certificates



[Miscellaneous](#)




[Type Test Certificates/Test Report](#)

Marine / Shipping	other	Environment			
	Miscellaneous	Confirmation	Miscellaneous		Environmental Confirmations

Environment
Environmental Confirmations

Дополнительная информация
Информация об упаковке Информация об упаковке Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/ru/ru/Catalog/product?mlfb=3VA9257-0EK11 Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/ru/ps/3VA9257-0EK11 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9257-0EK11

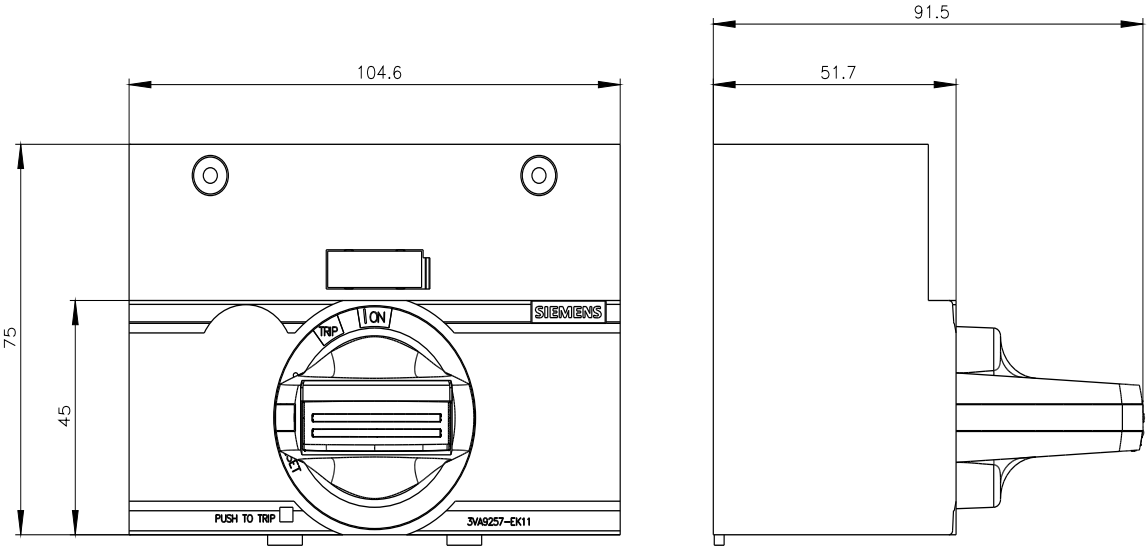

последнее изменение:

21.07.2022

