

плоский винтовой контакт, 3 шт. принадлежность для: 3VA1 400/630 3VA2 400/630



версия	
торговая марка изделия	SETRON
принадлежности	плоский винтовой контакт
Соединения согласно IEC	
толщина / шинопровода	0
• мин.	
• макс.	
толщина / шинопровода / макс.	0,4 мм
ширина / шинопровода / макс.	35 mm
Соединения согласно UL	
толщина / шинопровода / макс.	0,4 in
Сертификаты	
General Product Approval	EMV



[Miscellaneous](#)



Test Certificates	Marine / Shipping	other	Environment		
Type Test Certificates/Test Report	 LRS	Miscellaneous	Confirmation	Miscellaneous	Environmental Confirmations

Environment
Environmental Confirmations

Дополнительная информация
Информация об упаковке Информация об упаковке Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/ru/ru/Catalog/product?mlfb=3VA9403-0QA00 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/ru/ps/3VA9403-0QA00>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9403-0QA00

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

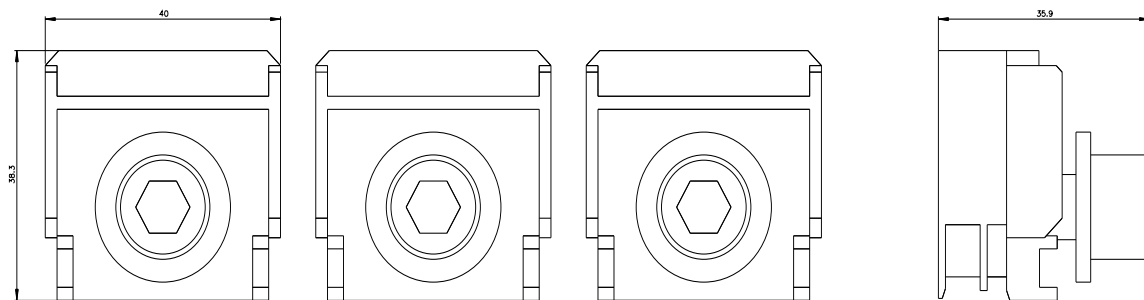

последнее изменение:

19.08.2022 

