

фронтальный поворотный привод стандарт МЭК IP30/40 принадлежность для:
3VA1 250



версия		
торговая марка изделия		SETRON
принадлежности		фронтальный поворотный привод
Общие технические данные		
степень защиты IP		IP30
Механическая конструкция		
высота		75 mm
ширина		105 mm
глубина		95 mm
Сертификаты		
General Product Approval		EMV
		Test Certificates



[Miscellaneous](#)




[Type Test Certificates/Test Report](#)

Marine / Shipping	other	Environment			
	Miscellaneous	Confirmation	Miscellaneous		Environmental Confirmations

Environment
Environmental Confirmations

Дополнительная информация
Информация об упаковке Информация об упаковке Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/ru/ru/Catalog/product?mlfb=3VA9257-0EK11 Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/ru/ps/3VA9257-0EK11 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9257-0EK11

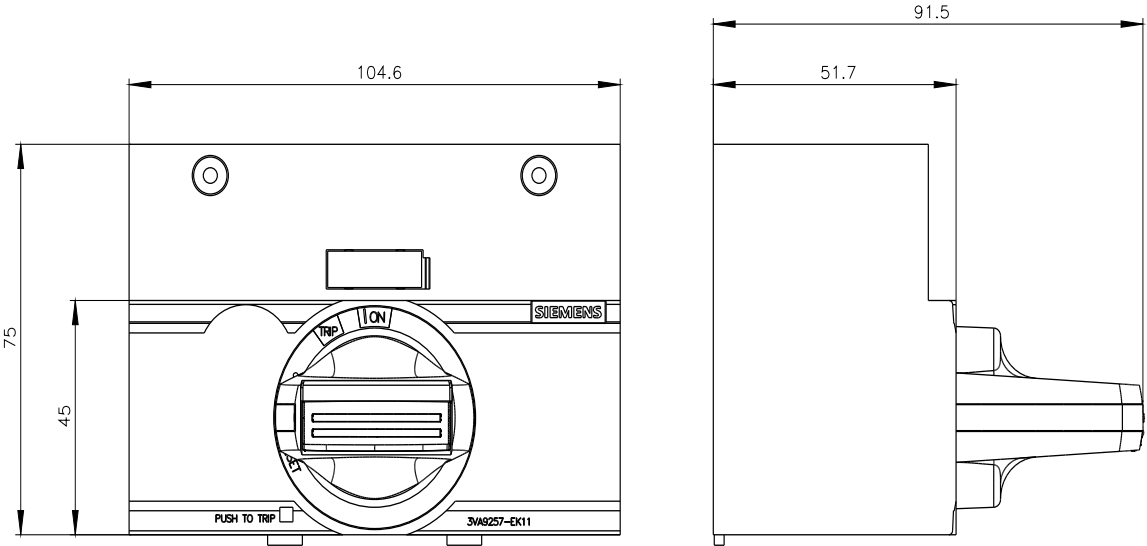

последнее изменение:

21.07.2022

