



активатор и расцепитель TD300 вкл. соед. кабель 3VA-TD300  
принадлежность для: 3VA2

версия	
торговая марка изделия	SENTRON
принадлежности	Контрольный прибор
Общие технические данные	
монтажное положение	любой
степень защиты IP	IP30
Механическая конструкция	
число автоматических выключателей / прямого подключения	1
высота	107 mm
ширина	76 mm
глубина	25 mm
окружающая температура / при эксплуатации	
• мин.	-10 °C
• макс.	40 °C
окружающая температура / при хранении	
• мин.	-40 °C
• макс.	50 °C
окружающая температура / при хранении	
• мин.	-40 °C
• макс.	50 °C

Сертификаты	
General Product Approval	EMV
	Test Certificates



[Miscellaneous](#)



[Type Test Certificates/Test Report](#)

Marine / Shipping	other	Dangerous goods	Environment
-------------------	-------	-----------------	-------------



[Miscellaneous](#)

[Confirmation](#)

[Miscellaneous](#)

[Transport Information](#)



Environment	
-------------	--

[Environmental Confirmations](#)

[Environmental Confirmations](#)

## Дополнительная информация

Информация об упаковке

[Информация об упаковке](#)

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/ru/ru/Catalog/product?mlfb=3VA9987-0MA10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/ru/ps/3VA9987-0MA10>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3VA9987-0MA10](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9987-0MA10)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

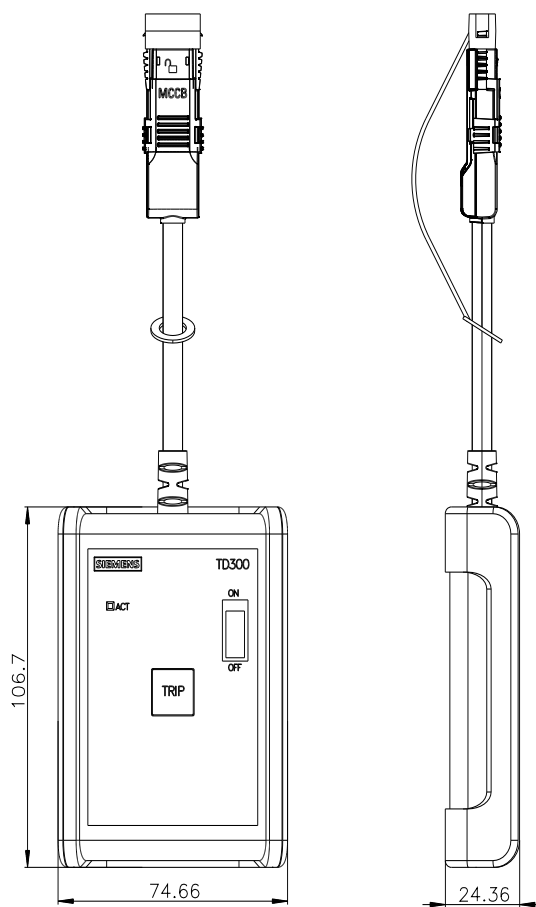

последнее изменение:

21.07.2022

